

## SEL-C963 Coaxial Cable for IRIG-B Distribution

RG-58A/U coaxial cable with ferrule connectors on both ends<sup>(1)</sup>

Part Number:

C	9	6	3	-			
---	---	---	---	---	--	--	--

### Length

Specify length—max length 130 feet (demodulated) and 500 feet (modulated) Enter length in feet with leading zeros. (Example: 5 feet = 005)


--	--	--	--	--	--	--	--

### Accessories

BNC Tee, Female, Male, Female (equipment mount)*	2 4 0 - 1 7 9 9
BNC Tee, Female, Female, Male (equipment mount)*	2 4 0 - 1 8 0 1
BNC Tee, Female, Female, Female (in-line, 3-way splice)*	2 4 0 - 1 8 0 2
BNC terminator, 50 ohm*	2 4 0 - 1 8 0 0
Wire-lead terminator, 50 ohm*	9 1 5 9 0 0 0 3 6

\* Additional Cost

<sup>(1)</sup> To verify your cable application, use the Cable Selector at <https://www.selinc.com/CableSelector/>.

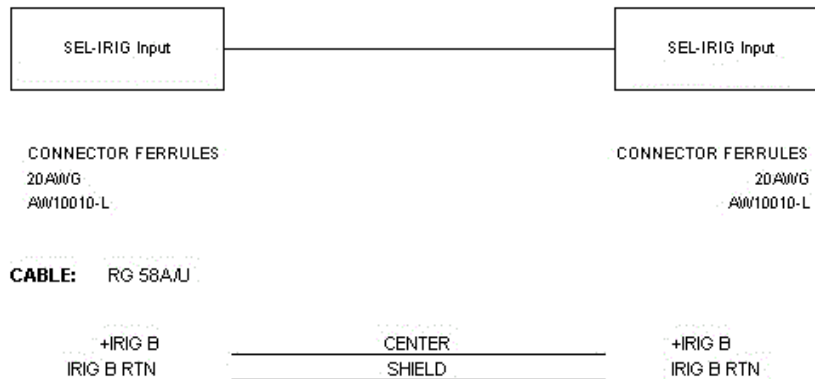

**Making Electric Power Safer, More Reliable, and More Economical®**

**SEL** SCHWEITZER ENGINEERING LABORATORIES, INC.

2350 NE Hopkins Court - Pullman, WA 99163 USA  
 Phone: +1.509.332.1890 - Fax: +1.509.332.7990